


## PV 5.12.5 SKM8X45 GSG CUGALSN (306 105)



Figure without obligation

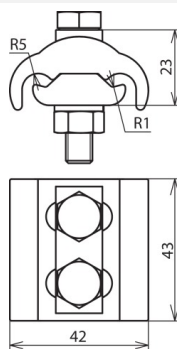

Clamp with spring washer for connecting/linking round conductors/cables in explosion-hazardous areas zone 1/21, 2/22. The clamp is secured against self-loosening according to DIN EN 62305-3 Supplement 2.

Arrangement:

Type	PV 5.12.5 SKM8X45 GSG CUGALSN
Part No.	306 105
Material of clamp	Cu/gal Sn
Clamping range Rd / Rd	5-12.5 mm
Clamping range (stranded / cable)	16-95 mm <sup>2</sup>
Screw	M8 x 45 mm
Material of screw / nut	StSt (V4A)
Material No.	1.4571 / 1.4404 / 1.4401
ASTM / AISI:	316Ti / 316L / 316
Type	with spring washer
Lightning impulse current (10/350 µs) (non-sparking)	25 kA
Short-circuit current (50 Hz) (0.1 s) (non-sparking)	1.65 kA
Lightning current carrying capability (10/350 µs)	100 kA /  25 kA <sup>*)</sup>
Standard	based on EN 62561-1
Weight	242 g
Customs tariff number (Comb. Nomenclature EU)	85389099
GTIN	4013364269125
PU	1 pc(s)

<sup>\*)</sup>For exact classification, see test certificate.

We reserve the right to introduce changes in performance, configuration and technology, dimensions, weights and materials in the course of technical progress. The figures are shown without obligation.