

MVK 8.10 SKM10X35 V4A (390 079)

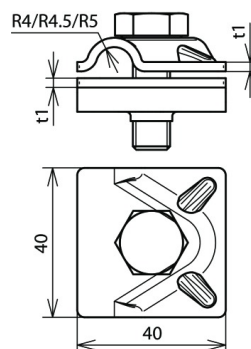
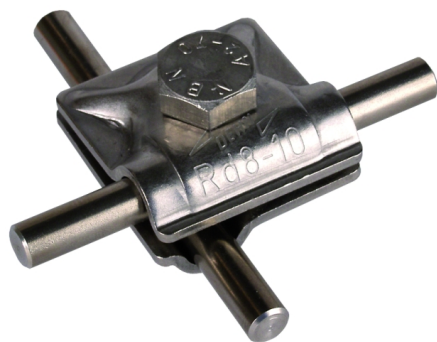


Figure without obligation

Clamp also suits for underground application.

| Type | MVK 8.10 SKM10X35 V4A |
|---|--------------------------|
| Part No. | 390 079 ✓ |
| Material of clamp | StSt (V4A) |
| Clamping range Rd | 8-10 mm |
| Material thickness (t1 / t2) | 2.5 mm |
| Screw | ● M10 x 35 mm |
| Material of screw / nut | StSt (V4A) |
| Material No. | 1.4571 / 1.4404 / 1.4401 |
| ASTM / AISI: | 316Ti / 316L / 316 |
| Standard | EN 62561-1 |
| Short-circuit current (50 Hz) (1 s; ≤ 300 °C) | 4.7 kA |
| Weight | 96 g |
| Customs tariff number (Comb. Nomenclature EU) | 85389099 |
| GTIN | 4013364128996 |
| PU | 50 pc(s) |

Note: Part No. 390 079 made of StSt (V4A) also suitable for underground application.

We reserve the right to introduce changes in performance, configuration and technology, dimensions, weights and materials in the course of technical progress. The figures are shown without obligation.