



RD 10 V2A R50M (860 950)

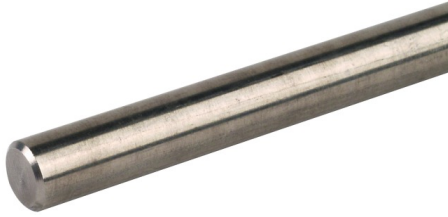


Figure without obligation

Stainless steel wire according to EN 62561-2, for use in lightning protection systems or equipotential bonding.

| Type | RD 10 V2A R50M |
|---|--------------------------------|
| Part No. | 860 950 ✓ |
| Diameter Ø conductor | 10 mm |
| Cross-section | 78 mm ² |
| Material | StSt |
| Material No. | 1.4301 / 1.4303 |
| Standard | based on EN 62561-2 |
| Conductivity | ≥ 1.25 m / Ohm mm ² |
| Resistivity | ≤ 0.8 Ohm mm ² / m |
| Weight | 617 g/m |
| Customs tariff number (Comb. Nomenclature EU) | 72210010 |
| GTIN | 4013364155596 |
| PU | 50 m |

We reserve the right to introduce changes in performance, configuration and technology, dimensions, weights and materials in the course of technical progress. The figures are shown without obligation.

Conductor materials will be delivered in original coil weights only.

More conductor materials and components as specified in the standard series EN 62561-2 upon request.