


DLH AL ZS 27 V2A (202 863)

Roof conductor holder with slotted saddle clamp for HVI power Conductor and Z-shaped connection lug for riveting or screwing to metal roofs.

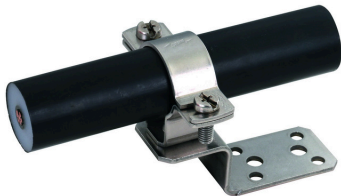

Type	DLH AL ZS 27 V2A
Part No.	202 863
Material of roof conductor holder	StSt
Material of conductor holder	StSt
Fixing	[4x] Ø5.2 / [2x] Ø6.5 mm
Material thickness	2.5 mm
Conductor support Rd	27 mm
Conductor routing	fixed
Screw	⬆ M8 x 25 mm
Standard	EN 62561-4
Weight	119 g
Customs tariff number (Comb. Nomenclature VAE)	85389099
GTIN	4013364354210
PU	25 Stk

